



# Facility, Security, and Pro A/V

Rhino™ 4200

All-Purpose Labelling Tool with QWERTY Keyboard



## Compact, time-saving labelling for on-the-go pros.

### Get labelling jobs done fast – and done right.

The new DYMO® Rhino™ 4200 gets labelling jobs done fast – and done right. Easily navigate the familiar QWERTY keyboard. Use one-touch “Hot Key” shortcuts to quickly create and format wire/cable wraps, flags, Code 39 and Code 128 barcodes, fixed-Length labels, breaker labels and more.

Print labels up to 19 mm wide in flexible nylon, permanent polyester and durable vinyl materials – PLUS print directly on heat-shrink tubes. Save even more time with great new features – like the ‘Favorites’ key which provides single-key access to commonly used labels, symbols and terms; and the ‘Custom’ key which eliminates repeated steps by saving customized settings.



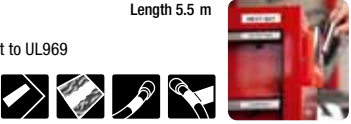



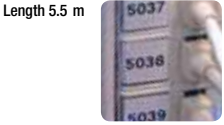




 


### DYMO® | Rhino™ 4200 features:

- 1 Easy to navigate computer-style QWERTY keyboard**  
Quick and comfortable text entry
- 2 One-Touch “Hot Keys” – a DYMO® exclusive**  
Shortcut keys for creating and formatting wire/cable wraps, flags, Code 39 and Code 128 bar codes, fixed-Length, general and breaker labels
- 3 Industrial-strength labelling versatility**  
Print 6 mm, 9 mm, 12 mm and 19 mm wide labels in a variety of materials and colours – PLUS print directly on heat-shrink tubes
- 4 NEW “Favorites” key**  
Single-key access to your most commonly used labels, symbols and terms
- 5 NEW “Custom” key prevents needless repetition**  
Customize and save settings for individual label formats



Up to

**19 mm**

IND	LABEL APPLICATIONS	LABEL COLOUR	24 mm label widths not for use with the Rhino™ 4200				
			6 mm	9 mm	12 mm	19 mm	24 mm
<b>Labels that stick and stay stuck.</b> DYMO® Industrial labels are tough— jobsite tested and UL recognized. Labels won't smear or fade and are built with industrial-strength adhesives to resist moisture, UV light and extreme temperatures. Whether you are labelling to OSHA, ISO and ANSI colour standards or labelling in harsh conditions, DYMO® Industrial labels have you covered. DYMO® Industrial labels are designed to work exclusively with Rhino™ printers and to perform on a variety of surfaces.  <b>LEARN MORE:</b> <a href="http://www.dymo.com/industrial">www.dymo.com/industrial</a>		BLACK ON WHITE	-	18443 <i>S0718580</i>	18444 <i>S0718600</i>	18445 <i>S0718620</i>	1805430
		BLACK ON YELLOW	-	-	18432 <i>S0718450</i>	18433 <i>S0718470</i>	1805431
		BLACK ON ORANGE	-	-	18435 <i>S0718490</i>	18436 <i>S0718500</i>	1805427
		BLACK ON GREY	-	-	1805413	1805419	1805425
		WHITE ON RED	-	-	1805416	1805422	1805429
		WHITE ON BLACK	-	1805437	1805435	1805436	1805432
		WHITE ON GREEN	-	-	1805414	1805420	1805426
<b>VINYL</b> - UL Recognized Component to UL969 - RoHS compliant 	Length 5.5 m 	WHITE ON BLUE	-	-	1805243	1805417	1805423
		WHITE ON PURPLE	-	-	1805415	1805421	1805428
		WHITE ON BROWN	-	-	1805412	1805418	1805424
<b>PERMANENT POLYESTER</b> - UL Recognized Component to UL969 - RoHS compliant 	Length 5.5 m 	BLACK ON WHITE	1805442	18482 <i>S0718240</i>	18483 <i>S0718210</i>	18484 <i>S0718220</i>	1734523 <i>S0773830</i>
		BLACK ON CLEAR	1805440	18508DMO <i>S0718160</i>	622289	622290	1805433
		BLACK ON METALLIC	1805441	18485 <i>S0718170</i>	18486 <i>S0718180</i>	18487 <i>S0718200</i>	1805434
<b>HEAT SHRINK TUBES</b> - UL Recognized Component to UL224 - Meets MIL-STD-202G, MIL-M-81531 & SAE-DTL 23053/5 (Class 1 & 3) - RoHS compliant 	Length 1.5 m 	BLACK ON WHITE	18051 <i>S0718260</i>	18053 <i>S0718280</i>	18055 <i>S0718300</i>	18057 <i>S0718330</i>	1805443
		BLACK ON YELLOW	18052 <i>S0718270</i>	18054 <i>S0718290</i>	18056 <i>S0718310</i>	18058 <i>S0718340</i>	1805444
<b>FLEXIBLE NYLON</b> - UL Recognized Component to UL969 - RoHS compliant 	Length 3.5 m 	BLACK ON WHITE	-	-	18488 <i>S0718100</i>	18489 <i>S0718120</i>	1734524 <i>S0773840</i>
		BLACK ON YELLOW	-	-	18490 <i>S0718080</i>	18491 <i>S0718090</i>	1734525 <i>S0773850</i>
<b>NON-ADHESIVE TAG</b> - RoHS compliant	Length 5.5 m 	BLACK ON WHITE	18111 <i>S0718350</i>	-	18113 <i>S0718380</i>	-	-
<b>SELF-LAMINATING</b> - RoHS compliant 	Length 5.5 m 	BLACK ON WHITE	-	-	-	-	1734821 <i>S0773860</i>

**Rhino™ 4200 SINGLE UNIT (BLISTER)**

Code: S0955950

**Box includes:**

- Rhino™ 4200 printer
- Quick reference guide
- 19 mm white flexible nylon tape

**Product specifications:**

- Runs on optional rechargeable lithium-ion battery pack or 6 AA batteries
- 1 year warranty + 1 year extra when registering
- Unit weight: 770 gr

**Optional accessories:**

- AC adapter Code: S0721430
- Rechargeable lithium-ion battery pack Code: S0895840

For more information or to find out your nearest distributor, please visit [www.dymo.com/industrial](http://www.dymo.com/industrial) or call us at +44 (0) 20 7341 5529.



©2011 DYMO®  
 DYMO bvba, Industriepark-Noord 30  
 B9100 Sint-Niklaas, Belgium  
[www.dymo.com/industrial](http://www.dymo.com/industrial)